



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

CERTIFICATE NO.: 2024010305668660

NAME AND ADDRESS OF THE APPLICANT

K.A. Schmersal GmbH & Co. KG
Moeddinghofe 30, D-42279 Wuppertal, Germany

NAME AND ADDRESS OF THE MANUFACTURER

K.A. Schmersal GmbH & Co. KG
Moeddinghofe 30, D-42279 Wuppertal, Germany

NAME AND LOCATION OF THE FACTORY

K.A. Schmersal GmbH & Co. KG
Moeddinghofe 30, D-42279 Wuppertal, Germany

PRODUCT NAME,MODEL AND SPECIFICATION

Door locking device

AV25, AV28;Ui:400V;Uimp:6kV;Ith:10A;AC-15: Ue/Ie: 230VAC/2A;DC-13: Ue/Ie:
200VDC/2A;Level of protection: IP20, IP41;See the Appendix for type description

STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS

GB/T 14048.5-2017

This is to certify that the above mentioned product(s) complies with the requirements of
implementation rules for compulsory certification(REFNO. CNCA-C03-02:2024).

Valid from: Aug.01,2024

Valid until: Jul.31,2029

The certificate information and validity could be checked by scanning the QR code below or logging in to
the website of the issuing authority, or on the website of the CNCA (www.cnca.gov.cn).



SIGNATURE:

谢肇煦



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.





CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

CERTIFICATE NO. : 2024010305668660

Appendix : Page 1 of 2

Type description:

AV25(1)(2)(3)(4)(5)(6)(7)(8)

AV28(1)(2)(3)(4)(5)(6)(7)(8)

Nr.	Option	Description
(1)	L	Left-hand version
	R	Right-hand version
(2)	Blank	Pull strap
	H	Lever H65
	H92	Lever H92
	H105	Lever H105
	B	Bearing block B
	B2	Bearing block B without cable gland
(4)	Blank	without auxiliary contact
	K	with auxiliary contact
(4)	Blank	Protection class com.cqc.cms.component.word.CertiAnnexDataModel IP 20
	IP 41	Protection class com.cqc.cms.component.word.CertiAnnexDataModel IP 41
(5)	Blank	without cable gland
	E4	Cable gland M20
	E1	Cable entry (5 holes)
(6)	X...	X-dimension = 11.5, 15, 20, 25, 30, 35, 40, 45 mm
	Z...	Z-dimension = 25 mm
(7)	U	Inclined section at locking bolt 45° bottom-side
	D	Inclined section at locking bolt 45° cover-side
	R	Inclined section at locking bolt 45° right-hand side
	L	Inclined section at locking bolt 45° left-hand side
(8)	Blank	back-side mounting holes (standard)
	GB215	frontal M8 mounting holes

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION


本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

CERTIFICATE NO. : 2024010305668660

Appendix : Page 2 of 2

	xxxx-xx	Indicator for minor customer -specific design change, without change for function or structure
		Combinations are possible

"X" and "Z" describe different penetration depths of the locking bolt in the frame.

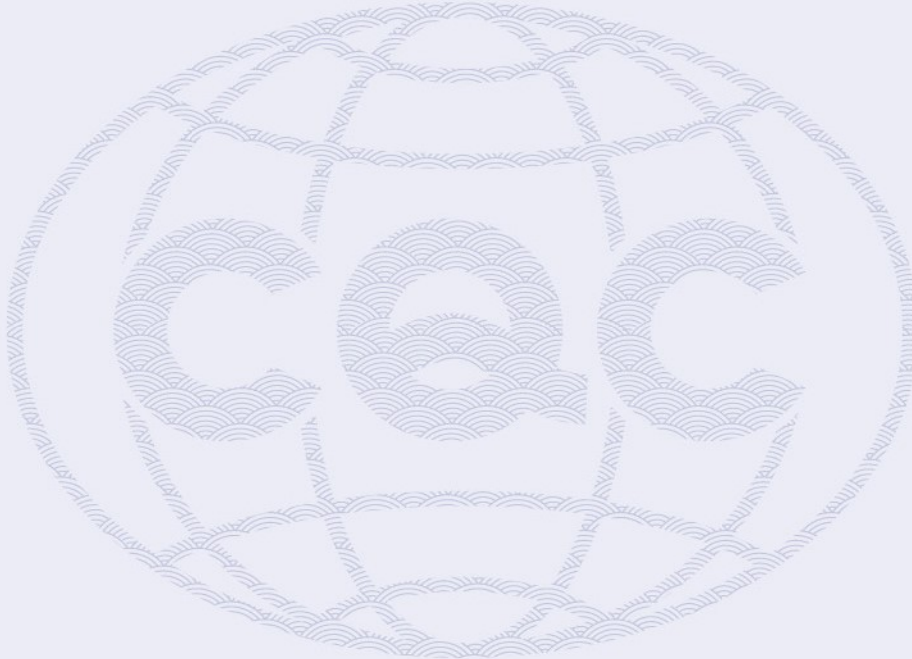

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.