



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

CERTIFICATE NO.: 2024010305668600

NAME AND ADDRESS OF THE APPLICANT

K.A. Schmersal GmbH & Co. KG
Moeddinghofe 30, D-42279 Wuppertal, Germany

NAME AND ADDRESS OF THE MANUFACTURER

K.A. Schmersal GmbH & Co. KG
Moeddinghofe 30, D-42279 Wuppertal, Germany

NAME AND LOCATION OF THE FACTORY

K.A. Schmersal GmbH & Co. KG
Moeddinghofe 30, D-42279 Wuppertal, Germany

PRODUCT NAME,MODEL AND SPECIFICATION

Micro Switch

M.6600, M. 6610, M. 6620;Ui:250V;Uimp:4kV;lth:4A ; AC-15:Ue/Ie:230VAC/1A;
IP65(M.6600),IP67(M.6610; M.6620);See the appendix

STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS

GB/T 14048.5-2017

This is to certify that the above mentioned product(s) complies with the requirements of
implementation rules for compulsory certification(REFNO. CNCA-C03-02:2024).

Valid from: Aug.01,2024

Valid until: Jul.31,2029

The certificate information and validity could be checked by scanning the QR code below or logging in to
the website of the issuing authority, or on the website of the CNCA (www.cnca.gov.cn).



SIGNATURE:

谢肇煦



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.





CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

CERTIFICATE NO. : 2024010305668600

Appendix : Page 1 of 2

Type description :

Ordering Code = M(1) (2)-(3)-K-(4)-(5)-(6)-(7)

| Nr. | Option | Description | 描述 |
|-----|---------|---|-------------------------------------|
| (1) | Blank | Basic switch / Standard type | 基本开关 / 标准类型 |
| | S | with rubber collar | 带橡胶套 |
| | 1S | with telescopic plunger, short | 带可调节直杆, 短 |
| | 2S | with telescopic plunger, long | 带可调节直杆, 长 |
| | 2R | with telescopic roller- plunger | 带可调节的滚轮直杆 |
| (2) | 6600 | rubber body with stainless-steel casing | 橡胶本体带不锈钢外壳 |
| | 6610 | glass-fibre reinforced body without mounting flange | 玻璃纤维增强本体不带安装法兰 |
| | 6620 | glass-fibre reinforced body with mounting flange | 玻璃纤维增强本体带安装法兰 |
| (3) | 10 | 1x NO contact | 1 常开 |
| | 11 | 1x NO contact, 1x NC contact | 1 常开, 1 常闭触点 |
| (4) | Y | IP Protection = IP 65 | IP 65 |
| | Z | IP Protection = IP 67 | IP 67 |
| (5) | Blank | Standard type (Cable length 0,5m) | 标准类型 (电缆长度 0,5m) |
| | „x“M | Cable attached; „x“: Indicator for length of cable in metres, e.g. “1,5M” | 连接电缆, “x”: 以米为单位的电缆长度指示器, 例如 “1,5M” |
| (6) | Blank | Standard type | 标准类型 |
| | xxxx-xx | Indicator for minor customer-specific design change, without change for function or structure | 针对客户特殊需求, 不改变产品结构和功能 |

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation


CERTIFICATE NO. : 2024010305668600

Appendix : Page 2 of 2

| | | | |
|-----|-------|------------------------|---------|
| | | | |
| (7) | Blank | Standard type | 标准类型 |
| | U | with roller turned 90° | 滚轮转 90° |

Remark: Order of blocks (5) and (6) may be reversed, no technical difference

备注：代码（5）和（6）的顺序可能颠倒，无技术差异

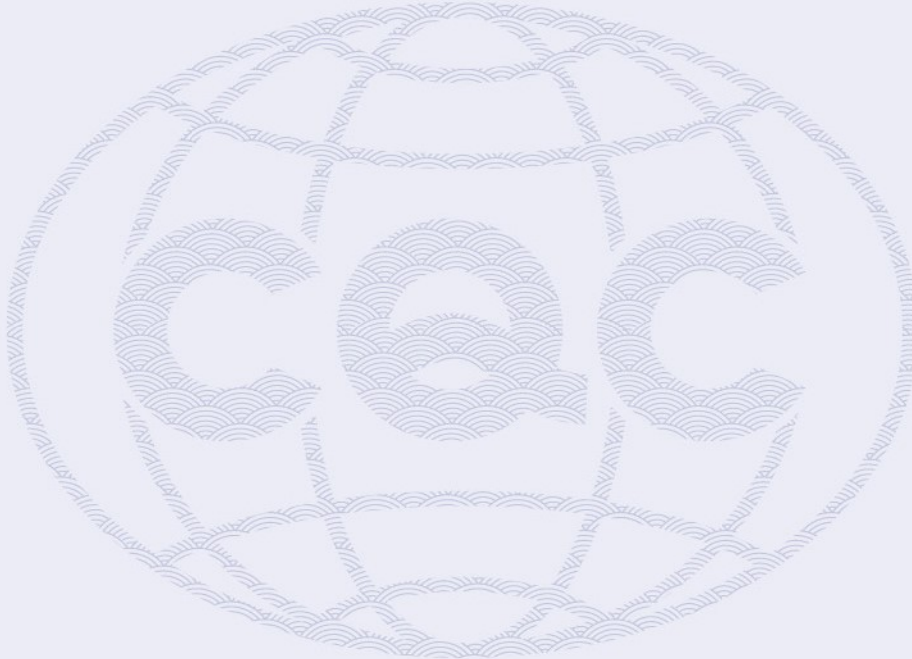

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.