



# CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，  
不得单独使用  
This translated document  
does not have legal validity and  
cannot be used in isolation

**CERTIFICATE NO.:** 2024010305668985

**NAME AND ADDRESS OF THE APPLICANT**

K.A. Schmersal GmbH & Co. KG  
Moeddinghofe 30, D-42279 Wuppertal, Germany

**NAME AND ADDRESS OF THE MANUFACTURER**

K.A. Schmersal GmbH & Co. KG  
Moeddinghofe 30, D-42279 Wuppertal, Germany

**NAME AND LOCATION OF THE FACTORY**

K.A. Schmersal GmbH & Co. KG  
Moeddinghofe 30, D-42279 Wuppertal, Germany

**PRODUCT NAME,MODEL AND SPECIFICATION**

Pull-Wire switch  
TQ215, TQ315, ZQ215, ZQ315;See the Appendix

**STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS**

GB/T 14048.5-2017

This is to certify that the above mentioned product(s) complies with the requirements of implementation rules for compulsory certification(REFNO. CNCA-C03-02:2024).

**Valid from:** Aug.01,2024

**Valid until:** Jul.31,2029

The certificate information and validity could be checked by scanning the QR code below or logging in to the website of the issuing authority, or on the website of the CNCA (www.cnca.gov.cn).



SIGNATURE:

谢肇煦



中国质量认证中心  
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.





# CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，  
不得单独使用  
This translated document  
does not have legal validity and  
cannot be used in isolation

CERTIFICATE NO. : 2024010305668985

Appendix : Page 1 of 3

TQ215, TQ315, ZQ215, ZQ315

Ui: 300V;


Uimp: 4kV;

Ith: 10A(Two contacts), 5A(Three contacts);

AC-15: Ue/Ie: AC240V/3A;

DC-13: Ue/Ie: DC24V/3A;

IP66, IP67。

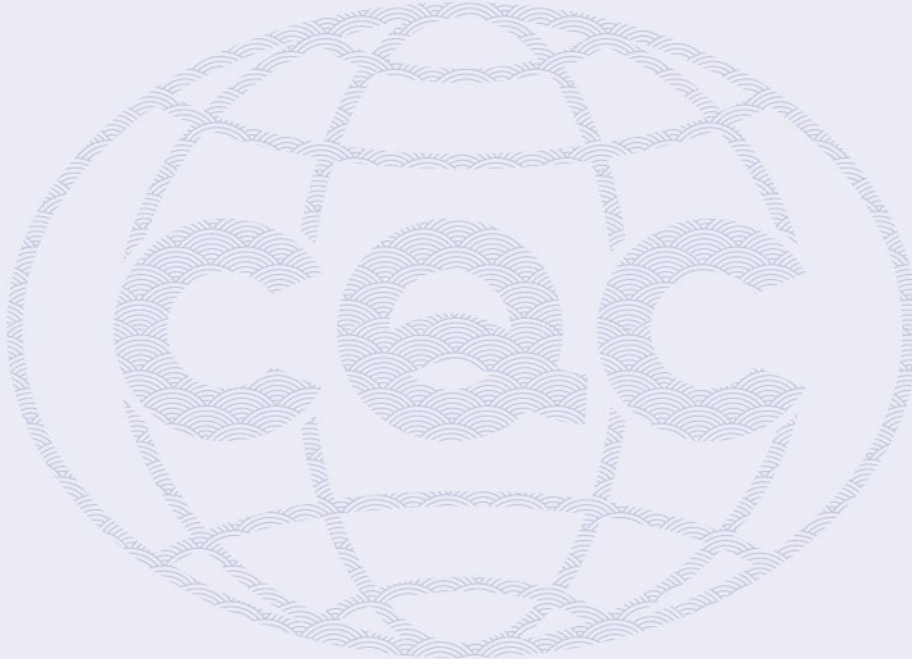

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心  
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.



# CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，  
不得单独使用  
This translated document  
does not have legal validity and  
cannot be used in isolation

CERTIFICATE NO. : 2024010305668985

Appendix : Page 2 of 3

Type description :

(1)Q(2)15(3)(4)-(5)(6)-(7)-(8)-(9)

No.	Option选项	Explanation	描述
(1)	Z	Snap action	速动
	T	Slow action	缓动
(2)	2	Main dimensions according EN50047	主要尺寸符合 EN50047
	3	Main dimensions according EN50041	主要尺寸符合 EN50041
(3)	Blank	Standard	标准类型
	L	Elongated hole	长孔
(4)	Blank	Standard	标准类型
	AR	Actuation Right Hand side	驱动右侧
	AL	Actuation Left Hand side	驱动左侧
(5)	11	1NO + 1NC	1 常开, 1 常闭触点
	02	2NC	2 常闭触点
	12	1NO + 2NC	1 常开, 2 常闭触点
	11UE	1NO + 1NC with overlapping(Slow action)	1 常开, 1 常闭触点, 交错触头, (缓动)
(6)	Blank	Standard	标准类型
	A1	Silver contact with gold coating 0,3µm	银触点镀金 0,3µm
	A2	Silver contact with gold coating 1µm	银触点镀金 1µm
	A3	Silver contact with gold coating 3µm	银触点镀金 3µm
(7)	Blank	Standard	标准类型
	G	LED	LED

This page is attached to the certificate and should be used at the same time as the certificate page.



**中国质量认证中心**  
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.



# CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，  
不得单独使用  
This translated document  
does not have legal validity and  
cannot be used in isolation

CERTIFICATE NO. : 2024010305668985

Appendix : Page 3 of 3

(8)	Blank	Standard (Cable entry M20)	标准类型 (M20 接线孔)
	M16	Cable entry M16 (215 type only)	M16 接线孔 (仅限 215 型)
	ST	Connector version	连接器版本
	STM	Connector version, metal	连接器版本, 金属
(9)	Blank	Standard type	标准类型
	XXXX-XX	Indicator for minor customer-specific design change, without change for function or structure	针对客户特殊需求, 不改变产品结构 and 功能

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心  
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.